

# CGL 125 N


Level Probes / Conductive Level Sensors

Max 16 Bar /Max 204°C

Connection 3/8"G

Diameter 5,8 mm

Length from 30 to 100 cm (check item codes listed below)

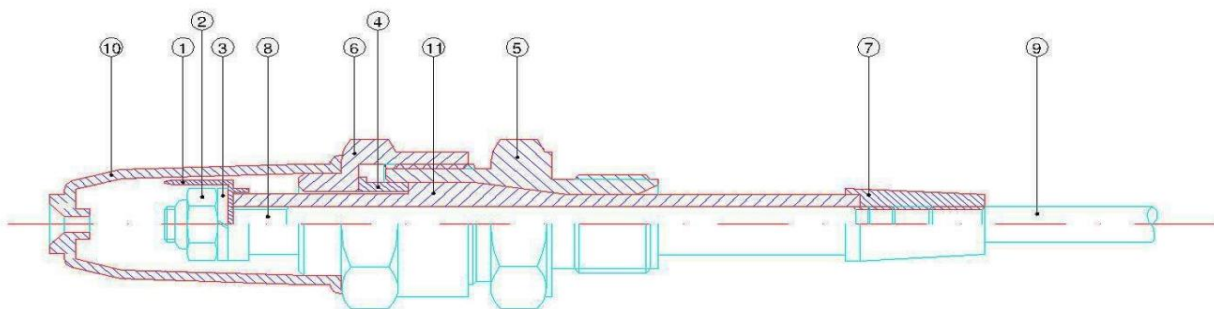

- 1) Faston 6.3 (AISI 304)
- 2) Self-blocking dice (Fe/Zn 8c1B)
- 3) Self-blocking dice (Fe/Zn 8c1B)
- 4) Socket (Ot 58)
- 5) External Body 3/8" (AISI 303)
- 6) pressure Socket (AISI 303)
- 7) Electrode Holder (AISI 303)
- 8) Pivot (AISI 303)
- 9) Electrode (AISI 304)
- 10) Rubber Protection (EPDM)
- 11) Insulator (PTFE G400)

## ITEM CODES

67020111	CGL125N-3 (30cm)
67020120	CGL125N-5 (50cm)
67020130	CGL125N-7 (70cm)
67020140	CGL125N-10 (100cm)